


Product sheet

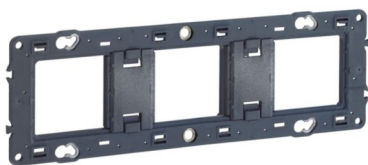

MOSAIC™ LEGRAND

Mosaic™ - Support - with site protection - for 6, 8 or 3 x 2 horizontal/vert. mod.

REF. 080253 | EAN. 3245060802530

[> Visit e-catalogue](#)

Product characteristics

- supports with site protection - For 6, 8 or 3 x 2 modules horizontal or vertical

Documentation

TECHNICAL DOCUMENTATION

 F00440FR-02.pdf | PDF (0.66Mo)

 F00440EN-02.pdf | PDF (0.66Mo)


CAD & Design specs / BIM

BIM-LEGRAND-CELIANE-2024-FRANCAIS.rvt | RVT (169.44Mo)

BIM-LEGRAND-MOSAIC-2023-FRANCAIS.rvt | RVT (128.48Mo)

BIM-LEGRAND-MOSAIC-2023-ENGLISH.rvt | RVT (126.68Mo)

CATALOGUE PAGE & OTHERS

 ex223001_1204.pdf | PDF (0.18Mo)

Agreements & Certificates

 OC / CB-FR_700177/A1 | (0.71Mo)

 B.B.J-B/12/006/24 | (3.34Mo)

 B.B.J-B/12/048/21 | (2.83Mo)

 NF-NF012_4236 | (0.53Mo)


 LGRP-00046-V01.01-FR.pdf | PDF (0.74Mo)

 OC / CB-FR_707532/M1 | (1.51Mo)

 LGRP-01211-V01.01-EN.pdf | PDF (0.71Mo)

 LGRP-00045-V01.01-FR.pdf | PDF (0.75Mo)

 OC / CB-FR_709693/M1 | (0.67Mo)

 OC / CB-FR_708376 | (1.33Mo)

 LGRP-01197-V01.01-FR.pdf | PDF (0.77Mo)

















 OC / CB-FR_707308/A3 | (4.23Mo)

 OC / CB-FR_720392 | (0.4Mo)

 OC / CB-HU-005022 | (0.62Mo)

 OC / CB-HU-005009-A1/M1 | (0.73Mo)

 LGRP-00991-V01.01-FR.pdf | PDF (0.71Mo)

-  NF-NF012_2201/A2 | (1.3Mo)
-  MEEI-UP 69258630 0001 | (0.23Mo)
-  NF-NF012_2513 | (1.2Mo)
-  LGRP-00942-V02.01-FR.pdf | PDF (0.86Mo)
-  B.B.J-B/12/047/21 | (2.9Mo)
-  AENOR-030/002285 | (0.47Mo)
-  NF-NF012_4512 | (0.86Mo)
-  OC / CB-FR_709703 | (1.06Mo)
-  NF-NF012_2666/M1 | (1.1Mo)
-  OC / CB-FR_705591/A3 | (0.73Mo)
-  OC / CB-FR_707077/M1 | (0.43Mo)
-  NF-NF012_2275/A2 | (0.96Mo)
-  NF-NF012_4239 | (0.53Mo)
-  LGRP-01279-V01.02-EN.pdf | PDF (0.7Mo)
-  B.B.J-B12/005/24 | (4.62Mo)
-  IRAM-DC-E-E100-003.1M2 | (2.18Mo)