


Product sheet

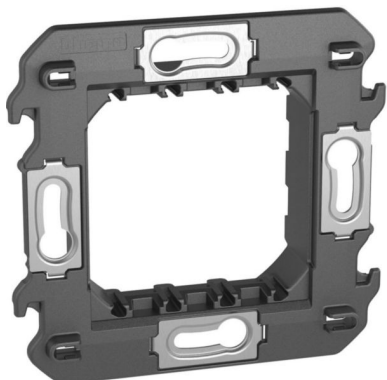

LIVING NOW BTICINO

Living Now - 2 modules support frame

REF. BT-K4702 | EAN. 8005543615188

[> Visit e-catalogue](#)

Product characteristics

- Maximum rigidity of the technopolymer that makes up this support makes it easy to install it on the wall
- Possibility of installation at half a step to guarantee maximum installation flexibility
- Equipped with protective valve to guarantee a perfect result without scratching or dirtying
- 2 modules, ultra-rigid black technopolymer
- Not equipped with screws that usually are already housed in the box

Recommendation / Restriction

- For internal use only.

The product's benefits

Installation

- The rigidity of the technopolymer makes easy to installation of this support frame on the wall. Possibility to install half step module.

Usage

- The protective valve, supplied with the support frame, allows to protect the devices installed during construction phases while ensuring visibility at the back

Avantages

- The maximum rigidity of the technopolymer, which makes up this support, makes it easy to install it on the wall
- The protective valve is supplied to protect the devices during the construction phases while ensuring visibility at the back

Documentation

TECHNICAL DOCUMENTATION

F02847EN-00.pdf | PDF (0.12Mo)

Agreements & Certificates

Decl. UE RED-A 4050 C | (0.45Mo)















OC / CB-FR_711679/A1 | (0.53Mo)

LGRP-01904-V01.01-FR.pdf | PDF (1.28Mo)

CAD & Design specs / BIM

BIM-BTICINO-LIVING-NOW-2024-ENGLISH.rvt | RVT (151.63Mo)

Bticino_appareillage_Living_Now_2023_FR.rvt | RVT (66.08Mo)

-  LGRP-01426-V01.01-EN.pdf | PDF (0.8Mo)
-  OC / CB-FR_717744 | (0.46Mo)
-  LGRP-01905-V01.01-FR.pdf | PDF (1.09Mo)
-  LGRP-01906-V01.01-FR.pdf | PDF (1.12Mo)
-  OC / CB-HU-005073 | (0.59Mo)
-  OC / CB-HU-005071 | (0.59Mo)
-  LGRP-01906-V01.01-EN.pdf | PDF (1.14Mo)
-  LGRP-01905-V01.01-EN.pdf | PDF (1.15Mo)
-  LGRP-01904-V01.01-EN.pdf | PDF (1.26Mo)
-  OC / CB-FR_717747 | (0.45Mo)
-  LGRP-01388-V01.01-EN.pdf | PDF (0.71Mo)
-  OC / CB-HU-005165 | (0.61Mo)
-  LGRP-01900-V01.01-FR.pdf | PDF (0.77Mo)
-  Decl. UE RED-A 4049 C | (0.45Mo)
-  LGRP-01357-V01.01-EN.pdf | PDF (0.71Mo)