


Product sheet

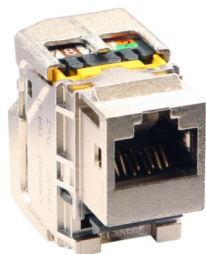

LCS² LEGRAND

LCS² - Keystone RJ 45 socket category 6 STP fast crimping connection

REF. 033154 | EAN. 3245060331542

RJ45 connector equipped with a rotating locking system. Suitable for category 6 U/UTP AWG 22 single-core cables up to AWG 26 and AWG multicore cables. It enables high speed data transmission.

> [Visit e-catalogue](#)

Description

RJ45 connector equipped with a rotating locking system. Suitable for category 6 U/UTP AWG 22 single-core cables up to AWG 26 and AWG multicore cables. It enables high speed data transmission.

Product characteristics

- Category 6A STP : Data rate up to 10 GigaBit/s. This allows you to download a 1 GigaBytes file in 1 second.
- With fast crimping connection
- Accepts the following cable connectors : RJ11 (4 contacts), RJ12 (6 contacts), RJ45 (9 contacts).

Recommendation / Restriction

- Max. number of connections and disconnections: 5 without refreshing the cable. Conform to standards ISO/IEC 11801 Ed. 3.0, EN 50173-1 and TIA/EIA 568 C

Documentation

TECHNICAL DOCUMENTATION

→ [LE02966AG.pdf](#) | PDF (0.94Mo)

 [F01422EN-03.pdf](#) | PDF (1.41Mo)

Agreements & Certificates

 [LGRP-01128-V02.01-EN.pdf](#) | PDF (0.91Mo)

 [LGRP-01128-V02.01-FR.pdf](#) | PDF (0.87Mo)

The product's benefits

Installation

- The RJ45 connectors are equipped with a rotating locking system that does not require special tools and enables rewiring in the event of error. Can be integrated in several supports : Axolute, Living Light, Light Tech, Matix.

Usage

- High reliability : 2500 movements (plug insertion/withdrawal)

CATALOGUE PAGE & OTHERS

 [ex223001_0982.pdf](#) | PDF (0.08Mo)