


# Product sheet

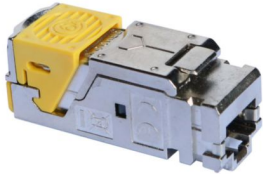

LCS<sup>3</sup> LEGRAND

6 connectors RJ45 Category 6A STP

REF. 033775 | EAN. 3414970870759

This RJ45 connector is to be installed in flat or angled (1U 24 and 48 slots) patch panels. Front-panel and fast-snap accessibility of each individual connector provide ease and reliability for tool-less installation and maintenance.

> [Visit e-catalogue](#)

## Description

This RJ45 connector is to be installed in flat or angled (1U 24 and 48 slots) patch panels. Front-panel and fast-snap accessibility of each individual connector provide ease and reliability for tool-less installation and maintenance.

### Product characteristics

- 568 A/B marking
- POE + compliant

### Recommendation / Restriction

- Compliant with ISO/IEC 11801 edition 3.0 (2017) and EIA/TIA 568 C2-1 standards

## The product's benefits

### Installation

- User installation is rendered easy through an intuitive fast and secure management of each individual connector.

### Usage




- Daily user maintenance is rendered easy through the move-add-change management of each cassette and individual connector.

### Avantages



- Connector tested and guaranteed to support POE signals (standard IEEE 802.3af and POE+, draft standards 802.3at) up to 2500 connections and disconnections with load.
- Tests are carried out with 2 simultaneous POE+ circuits producing a minimum total power of 50W.

## Documentation


### TECHNICAL DOCUMENTATION




















-  S000096850FR-06.pdf | PDF (8.19Mo)
-  S000096850EN-06.pdf | PDF (8.19Mo)
-  LE09819AB.pdf | PDF (1.07Mo)

### Agreements & Certificates

-  AoC-CL4\_Cat6A\_STP\_32869\_ac1181045 | (0.08Mo)
-  AoC-PL2\_Cat6A\_FTP\_32778\_ac1171014 | (0.08Mo)

### CATALOGUE PAGE & OTHERS

-  ex223001\_0979.pdf | PDF (0.13Mo)
-  ex223001\_0982.pdf | PDF (0.08Mo)

-  LGRP-00626-V02.01-FR.pdf | PDF (0.96Mo)
-  AoC-CL2\_Cat6A\_STP\_32777\_ac1171018A | (0.08Mo)
-  AoC-CL2\_Cat6A\_FFTP\_32799\_ac1171010 | (0.07Mo)
-  AoC-CL2\_Cat6A\_FTP\_32778\_ac1171015 | (0.08Mo)
-  AoC-PL3\_Cat6A\_FTP\_32778\_ac1171016 | (0.08Mo)
-  AoC-PL2\_C6A\_UFTP\_32884\_ac1191058 | (0.06Mo)
-  AoC-PL2\_Cat6A\_FFTP\_32799\_ac1171009 | (0.07Mo)
-  AoC-4PPoE 2019-676 Ac Delta Force | (0.08Mo)
-  AoC-PL2\_Cat6A\_STP\_32777\_ac1171017A | (0.08Mo)
-  AoC-CL2\_C6A\_UFTP\_32884\_ac1191059 | (0.06Mo)
-  AoC-CL2\_C6A\_STP\_32882\_ac1191063 | (0.06Mo)
-  AoC-CL4\_Cat6A\_STP\_32778\_ac1181044 | (0.08Mo)
-  AoC-Composant Cat6A STP 3P-1200331 | (0.06Mo)
-  AoC-CL2\_C6A\_FFTP\_32883\_ac1191061 | (0.06Mo)
-  AoC-PL2\_C6A\_FFTP\_32883\_ac1191060 | (0.06Mo)
-  LGRP-00626-V02.01-EN.pdf | PDF (0.95Mo)
-  AoC-PL3\_Cat6A\_STP\_32777\_ac1171019A | (0.08Mo)
-  AoC-PL2\_C6A\_STP\_32882\_ac1191062 | (0.06Mo)
-  AoC-PL3\_Cat6A\_FFTP\_32799\_ac1171011 | (0.07Mo)