


Product sheet

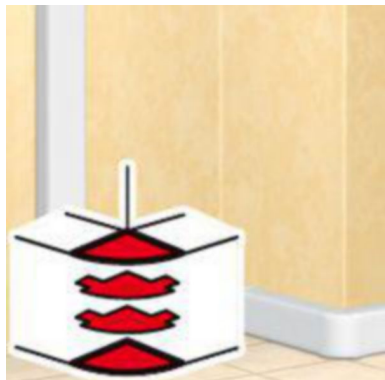

DLP LEGRAND

Variable external angle for DLP universal trunking 3 compartments 50x170mm or 50x220mm

REF. 010638 | EAN. 3245060106386

[> Visit e-catalogue](#)

Product characteristics

- Variable external angle of 60 to 120 degrees
- Respect the protection index
- Improvement of aesthetics (covering of the cut)
- Delivered with junctions of partition
- Colour: white

The product's benefits

Installation

- Clippes directly on the body of the trunking (with or without separation partition)

Usage

- The external angles ensure the continuity of the flexible cover on the angles, hence preventing cut of cover and being aesthetic

Documentation

TECHNICAL DOCUMENTATION

 F00885EN-04.pdf | PDF (1.66Mo)

 F00885FR-03.pdf | PDF (1.99Mo)

CAD & Design specs / BIM

BIM-LEGRAND-TRUNKING-EXPORT-2024.rvt | RVT (14.36Mo)

BIM-LEGRAND-GOULOTTES-FRANCE-2024.rvt | RVT (13.17Mo)


BIM-LEGRAND-GOULOTTES-BELGIQUE-2024.rvt | RVT (23.93Mo)

CATALOGUE PAGE & OTHERS

 ex223001_1071.pdf | PDF (0.11Mo)

 ex223001_1074-1075.pdf | PDF (0.12Mo)

Agreements & Certificates

 NF 004-601796A | (0.42Mo)

 LGRP-01605-V02.01-FR.pdf | PDF (0.71Mo)

 LGRP-01605-V02.01-EN.pdf | PDF (0.75Mo)