


# Product sheet

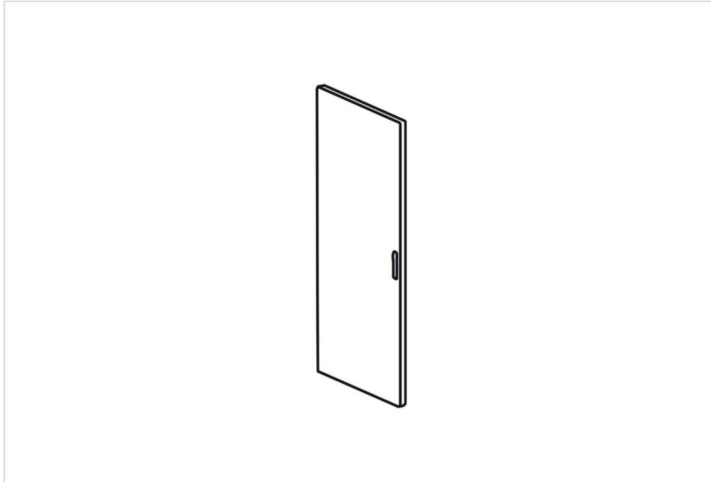

## LEGRAND

Reversible curved metal door XL<sup>3</sup> 4000 - width 725 mm  
- Height 2000 mm

REF. 020554 | EAN. 3245060205546

[> Visit e-catalogue](#)

## Product characteristics

- Distribution enclosures XL<sup>3</sup> 4000 - IP 30 - IK 07 - IP 55 - IK 08 with door and sealing kit for use when joining enclosures - Consist of the combination of a "roof - base" assembly, structural uprights, functional uprights, rear and side panels RAL 7035, plinths RAL 7004 - Height 2000 or 2200 mm. - Capacity 24 modules (enclosures width 725 or width 975 with internal cable sleeve), 36 modules (enclosures width 975) - Usable faceplate height 1800 mm (1700 mm only if using the pivoting support frame) or 2000 mm
- Reversible doors - Supplied with handle - Interchangeable key barrels, to be ordered separately - For mounting on Front, rear or side Curved - metal - Width 725 mm - Height : 2000 mm

## Documentation

### TECHNICAL DOCUMENTATION

→ [F0996C-02.pdf](#) | PDF (0.37Mo)

[EXB15002\\_CA\\_XL3-4000-6300\\_EN.pdf](#) | PDF (51.43Mo)

### CAD & Design specs / BIM

[Legrand\\_Armoire\\_XL<sup>3</sup>\\_4000\\_gaine\\_à\\_câble.rfa](#) | RFA (0.51Mo)

[Legrand\\_Distribution\\_enclosure\\_XL<sup>3</sup>\\_4000\\_external\\_cables\\_sleeves.rfa](#) | RFA (0.51Mo)

[Legrand\\_Armoire\\_XL<sup>3</sup>\\_6300-4000.rfa](#) | RFA (0.54Mo)

[Legrand\\_Distribution\\_enclosure\\_XL<sup>3</sup>\\_6300-4000.rfa](#) | RFA (0.54Mo)

### CATALOGUE PAGE & OTHERS

[ex223001\\_0381.pdf](#) | PDF (0.46Mo)

### Agreements & Certificates

[LOVAG-IT 12.017](#) | (0.13Mo)

[LOVAG-IT 12.019](#) | (0.59Mo)

[LOVAG-IT 13.045](#) | (0.12Mo)