


Product sheet

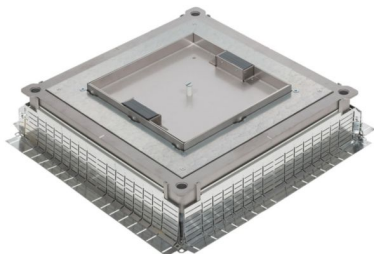

MOSAIC™ LEGRAND

Floor box for thick wooden floor - IP30 - with 2 lateral cable exits

REF. 089688 | EAN. 3245060896881

[> Visit e-catalogue](#)

Product characteristics

- Allow the distribution of strong or low currents in concrete floor
- 2 lateral cable exits
- IP30
- 24 modules
- Supplied with all necessary wiring accessories supports

Recommendation / Restriction

- Temperature of use, transport and storage: -5° à +60°

Documentation

TECHNICAL DOCUMENTATION

→ [LE01716AB-05.pdf](#) | PDF (3.32Mo)

 [F00839EN-05.pdf](#) | PDF (0.89Mo)

 [F00839FR-05.pdf](#) | PDF (0.93Mo)

CAD & Design specs / BIM

[Legrand-heavy-duty-floor-boxes-EN.rfa](#) | RFA (1Mo)

[Legrand-boites-de-sol-charge-lourde-FR.rfa](#) | RFA (1Mo)

The product's benefits

Installation

- Before fitting coating, adjustment of the level of the inside of the cover with the help of the glue (depth of the glue = difference between the coating thickness and the cover height)

CATALOGUE PAGE & OTHERS

 [ex223001_1164.pdf](#) | PDF (0.11Mo)