


Product sheet

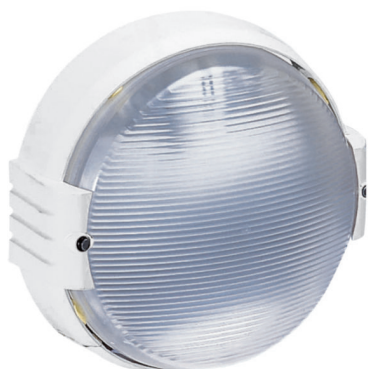

LEGRAND

Bulkhead light Koro - vandal-resistant - IP55 - IK09 - 100 W- E27 - round

REF. 062415 | EAN. 3245060624156

[> Visit e-catalogue](#)

Product characteristics

- IP 44/54/55 weatherproof bulkhead lights - For domestic, commercial areas and tough environments
- IP 55 - IK 08 round Koro bulkhead light class II - For risk situation, indoors and outdoors tough. environments , internal and external applications IP 55 - IK 09 - class II - Security assured by covering trim - Locked with 2 special screws which may be locked with key Cat.No 0 919 45 - Shock - resistant polycarbonate diffuser - Opening can be reversed Right / Left supplied with 1 Plexo membrane gland - Through - wiring or terminal connection (side or rear) - White - E 27 - Round for E27 - 70 W halogen or 20 W compact fluorescent lamps

Documentation

TECHNICAL DOCUMENTATION

- [0064AC511.pdf](#) | PDF (1.31Mo)
- [S000092755FR_1.pdf](#) | PDF (0.53Mo)

CATALOGUE PAGE & OTHERS

- [ex223001_0901.pdf](#) | PDF (0.09Mo)
- [ex223001_0902.pdf](#) | PDF (0.09Mo)