


Product sheet

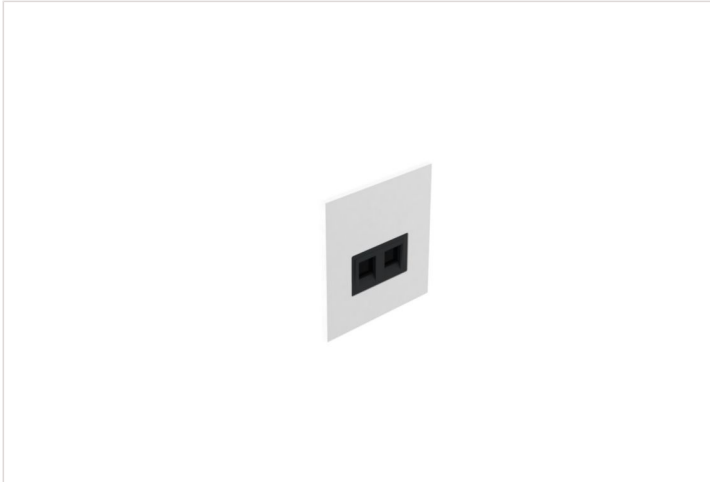

ART D'ARNOULD LEGRAND

RJ45 socket category 6 UTP 2 modules Epure satin white

REF. AR-68342 | EAN. 3233625160270

[> Visit e-catalogue](#)

Product characteristics

- RJ45 Cat 6 : Data rate up to 1 GigaBit/s. This allows you to download a 1 GigaByte file in 8 seconds.
- Support high capacity PoE applications. Power over Ethernet pass electric power along with data on twisted pair Ethernet cabling.
- Equipped with a dust cover protecting the connector. Delivered with plates .
- 2 modules
- Satin white

Recommendation / Restriction

- For flush-mounting, back box has to be minimum 35mm deep. Conform to standards ISO/IEC 11801 Ed. 3.0, EN 50173-1 and TIA/EIA 568 C. Indoor use only.

The product's benefits

Installation

- Supplied with support frames and plates. Equipped with connectors with quick toolless connection.

Usage

- Suitable for commercial and residential installation. IP and analog phones. Very suitable for downloads, streaming or online games requiring low latency.

Avantages

- RJ45 connector is equipped with a locking nut. It does not require a special tool and can be re-wired if a mistake is made.
- Compatible with cords equipped with RJ11, RJ12 or RJ45 plugs.
- Slot system allows a perfect and easy multigang setting. The support frames can be perfectly joined thereby easing the installation. Can be installed in a normal (single) flush mounting box, no need to additional wall groove cutting or cabling.

Documentation

TECHNICAL DOCUMENTATION

 [F03075EN-00.pdf](#) | PDF (0.72Mo)

CATALOGUE PAGE & OTHERS

 [ex223001_0715.pdf](#) | PDF (0.08Mo)