


# Product sheet

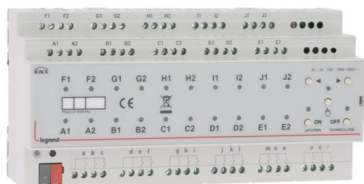

LEGRAND

KNX controller multi-applications din 20 outputs 18 inputs

REF. 002679 | EAN. 3414972052375

> [Visit e-catalogue](#)

## Product characteristics

- 20 outputs - 16A - 250 VAC 50/60 Hz - 4000 VA max
- 18 binary inputs
- DIN 10 modules
- Power supply from KNX bus ( 10mA)

## Recommendation / Restriction

- Configuration through ETS tool from KNX association

## The product's benefits

### Installation

- Connected with the BUS/KNX cable

### Usage

- All in one product for different room layouts such as apartments, hotel rooms, hospitals and residences: switching lighting, switching loads, controlling AC/DC blinds, controlling fan coils (2 & 3 point valve), dry contact inputs

### Avantages

- Grouped 4 outputs as 5 independent output channels configurable for different modes of operation: switching output x4, AC blind x2, DC blind x1, 2 Point valve x2, 3 point valve x1
- Suitable for switching resistive, capacitive and inductive loads as well as fluorescent lamp following several functions: staircase, external logic, internal logic, priority, threshold, operating hour, sweep
- Independent input channels operating as universal interface with following functions: switch / push button input, dimmer control, control of shutter/blinds, value sending, scene control, counter for count pulse


## Documentation

### TECHNICAL DOCUMENTATION

→ [LE12358AD.pdf](#) | PDF (0.62Mo)


### CATALOGUE PAGE & OTHERS

[ex223001\\_0896.pdf](#) | PDF (0.07Mo)


 S000114123EN\_4.pdf | PDF (4.97Mo)

 S000114123FR\_4.pdf | PDF (4.86Mo)

### Agreements & Certificates

 KNX EIB-11/16832/20 | (0.79Mo)

### Software & configurators

 LOG\_RA00205AA\_002679-V01.01.zip | ZIP (0.29Mo)