


# Product sheet

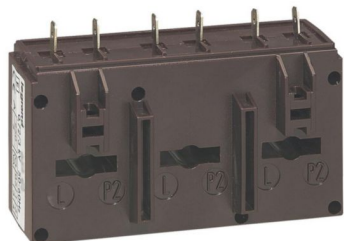

LEGRAND

Three phase current transformer (CT) - for three 20.5 x 5.5 mm bar - transformation ratio 250/5

REF. 412157 | EAN. 3414970593559





[> Visit e-catalogue](#)

## Product characteristics


- Current transformers (CT)
- Three - phase solid core current transformers - Used with ammeters, electricity meters or multi-function measuring units - Current at the secondary : 5 A - For Fixing directly on bars - Secondary connected by terminals or lugs - Precision class : 1 %For three 20,5 x 5,5 mm bars - Transformation ratio : 250/5 - Output : 3 VA

## Documentation

### TECHNICAL DOCUMENTATION

-  F01962FR-04.pdf | PDF (0.51Mo)
-  EXB20059\_GT\_EMDX3\_Transformateurs\_courant\_FR.pdf | PDF (2.96Mo)
-  F01962EN-03.pdf | PDF (0.52Mo)
-  EXB20060\_TG\_EMDX3\_Current\_transformers\_EN.pdf | PDF (2.98Mo)

### CATALOGUE PAGE & OTHERS

-  ex223001\_0127.pdf | PDF (0.07Mo)
-  ex223001\_0128.pdf | PDF (0.07Mo)